


4.4 Start/Stop

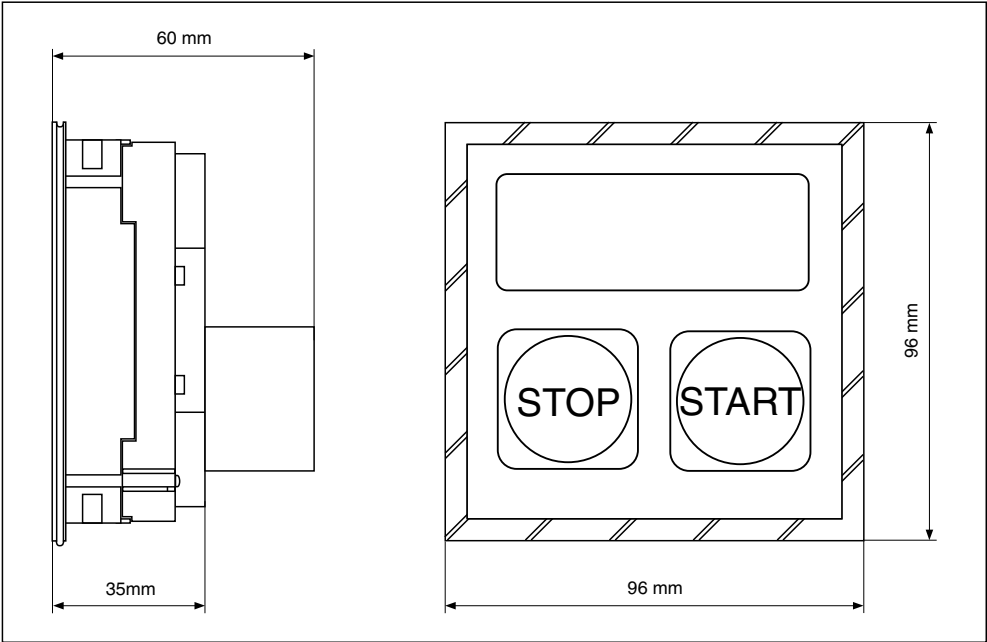

Technical Data	
Model Number	4E0080.01-090
Number of Keys	2 buttons (labeled START and STOP)
Temperature Range Operating Storage	0 to 50 °C (32 to 122 °F) -20 to 60 °C (-4 to 140 °F)
Relative Humidity Operating Storage	5 to 95 % (non-condensing) 5 to 95 % (non-condensing)
Shock	Conforms to IEC 60068-2-27 15g equivalent, 150 m/sec ² , 11 msec, 3 axes (positive and negative)
Vibration	Conforms to IEC 60068-2-6 1g equivalent, 10-58 Hz; 0.075 mm 58-150 Hz; 9.8m/sec ² 20 cycles per axis