


3.3 Keypad Module 12+4 Keys

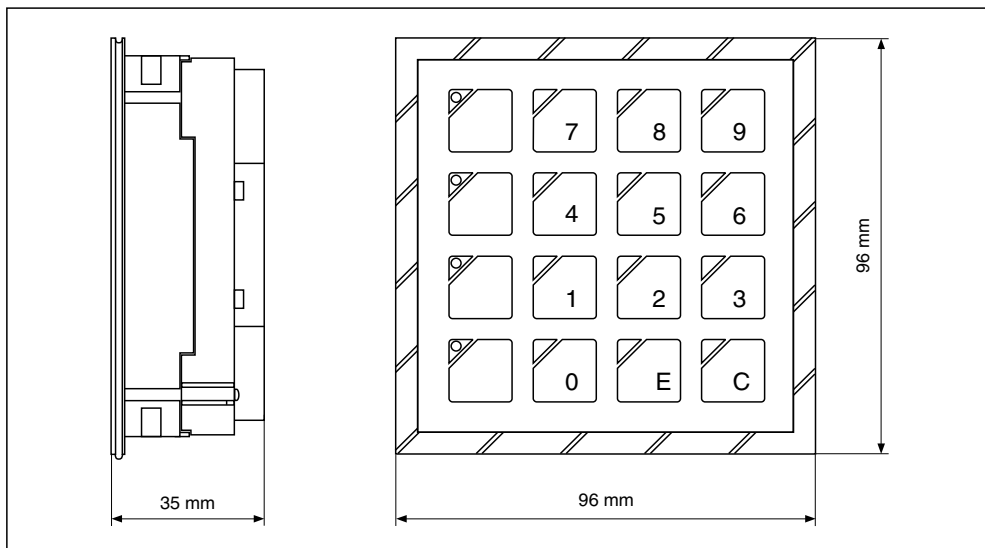

Technical Data	
Model Number	4E0021.01-090
Number of Keys	16 short stroke keys
Number of LEDs	4 (yellow)
Labeling	12 keys are labeled as a number block 4 keys can be labeled by the user
Temperature Range Operating Storage	0 to 50 °C (32 to 122 °F) -20 to 60 °C (-4 to 140 °F)
Relative Humidity Operating Storage	5 to 95 % (non-condensing) 5 to 95 % (non-condensing)
Shock	Conforms to IEC 60068-2-27 15g equivalent, 150 m/sec ² , 11 msec, 3 axes (positive and negative)
Vibration	Conforms to IEC 60068-2-6 1g equivalent, 10-58 Hz; 0.075 mm 58-150 Hz; 9.8m/sec ² 20 cycles per axis
Current Requirements	1.5 mA at 24 VDC (each LED requires an additional 3 mA when lit)